


Thermistors

Dimensions: mm (in)

50 mm (2") STAINLESS STEEL TUBULAR THERMISTOR

- SHEATH MATERIAL — STAINLESS STEEL
- SHEATH DIA. — 3 (1/8)
- SHEATH LENGTH — 50 (2)
- WIRE AWG — 26
- WIRE INSULATION — PFA
- TERMINATION — STRIPPED LEADS

 OSK3108
\$63 each
 Plus One-Time Set-Up Charge



THERMISTOR WIRE WITH TA3F CONNECTOR TERMINATION

- WIRE LENGTH — 5.5 m (18 feet)
- TERMINATION — TA3F CONNECTOR


OSK22542
\$30 each
 Plus One-Time Set-Up Charge



SOLID STATE TEMPERATURE SENSOR WITH PFA INSULATED WIRE

- CALIBRATION — K
- SHEATH DIA. — 6 (1/4)
- SHEATH LENGTH — 38 (1-1/2)
- WIRE AWG — 26
- WIRE LENGTH — 900 (36)
- WIRE INSULATION — PFA
- TERMINATION — STRIPPED LEADS

 
OSK4018
\$62 each
 Plus One-Time Set-Up Charge



PROBE WITH BLACK SHRINK TUBING AND PHONE TERMINATION

- SHEATH MATERIAL — VINYL
- SHEATH LENGTH — 330 (13)
- WIRE LENGTH — 3 m (10 feet) LEADS
- TERMINATION — PHONE PLUG


OSK1009
\$127 each
 Plus One-Time Set-Up Charge

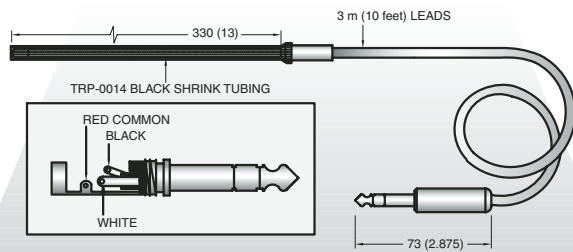

SOLID STATE TEMPERATURE SENSOR IN A STAINLESS STEEL TUBE WITH SMP MALE CONNECTOR TERMINATION

- CALIBRATION — K
- SHEATH MATERIAL — 316 STAINLESS STEEL
- SHEATH LENGTH — 152 (6)
- WIRE LENGTH — 152 (6)
- WIRE INSULATION — PFA
- TERMINATION — SMP MALE CONNECTOR


OSK4595
\$89 each
 Plus One-Time Set-Up Charge

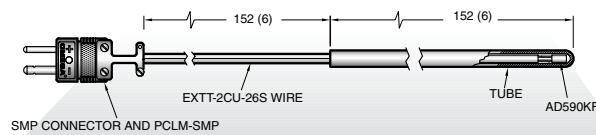

THERMISTOR WITH PIPE FITTING

- SHEATH MATERIAL — PFA COATED
- SHEATH DIA. — 3 (1/8)
- SHEATH LENGTH — 89 (3-1/2)
- TERMINATION — STRIPPED LEADS

 
OSK1769
\$168 each
 Plus One-Time Set-Up Charge



LINEAR THERMISTOR PROBE WITH HARDENED STEEL TUBE

- SHEATH MATERIAL — 304 STAINLESS STEEL
- SHEATH DIA. — 3 (1/8)
- SHEATH LENGTH — 203 (8)
- WIRE LENGTH — 2 m (7 feet)
- TERMINATION — STRIPPED LEADS


OSK1318
\$119 each
 Plus One-Time Set-Up Charge

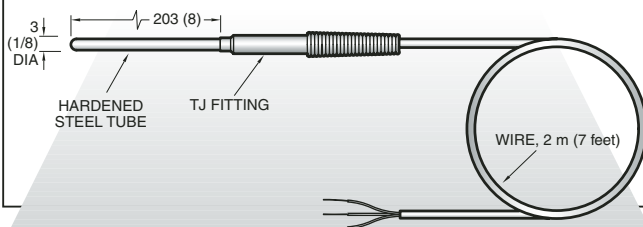

THERMISTOR WITH STAINLESS STEEL CUP FOR SURFACE TEMPERATURE

- SHEATH LENGTH — 300 (12)
- WIRE LENGTH — 3 m (10 feet)
- TERMINATION — PHONE PLUG

OSK1152
\$125 each
 Plus One-Time Set-Up Charge

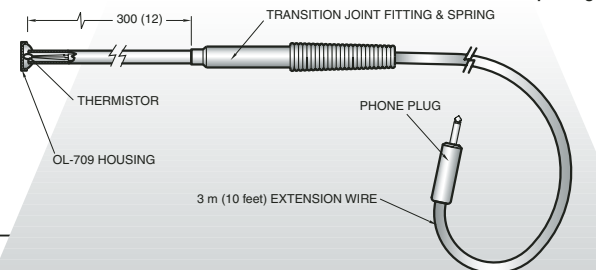


Thermistors (cont'd)

THERMISTOR WITH LONG LEADS AND RR-100 CONNECTOR

- SHEATH LENGTH — 300"
- TERMINATION — RR-100 CONNECTOR


OSK2187
\$99 each
 Plus One-Time Set-Up Charge

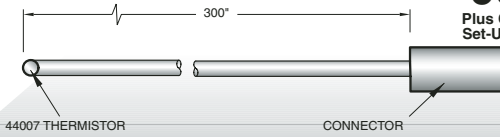

8 1/4" THERMISTOR PROBE WITH NPT FITTING

- SHEATH DIA. — 1/8"
- SHEATH LENGTH — 8-1/4"
- WIRE LENGTH — 10'
- TERMINATION — STRIPPED LEADS


OSK2853
\$82 each
 Plus One-Time Set-Up Charge

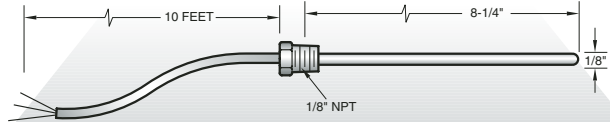

HOLLOW TUBE THERMISTOR

- SHEATH MATERIAL — 316 STAINLESS STEEL
- SHEATH DIA. — 1/8"
- SHEATH LENGTH — 10"
- WIRE LENGTH — 12"
- TERMINATION — THERMISTOR AT ONE END AND STRIPPED LEADS AT OTHER

 
OSK1184
\$55 each
 Plus One-Time Set-Up Charge



SOLID STATE TEMPERATURE SENSOR

- CALIBRATION — K
- SHEATH MATERIAL — STAINLESS STEEL
- SHEATH DIA. — .250"
- SHEATH LENGTH — 4.00"
- WIRE AWG — 20
- WIRE LENGTH — .50"
- TERMINATION — STRIPPED LEADS


OSK3294B
\$112 each
 Plus One-Time Set-Up Charge

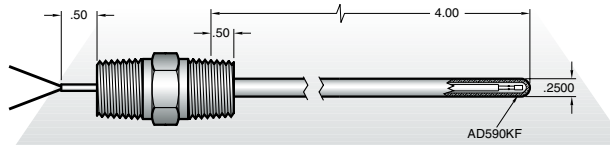

GENERAL PURPOSE THERMISTOR PROBE WITH 180° BEND

- SHEATH MATERIAL — 304 STAINLESS STEEL
- SHEATH DIA. — 1/8" O.D.
- SHEATH LENGTH — 8"
- TERMINATION — OTP-COPPER MALE CONNECTOR


OSK70533
\$87 each
 Plus One-Time Set-Up Charge

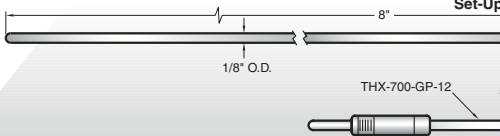

5' THERMISTOR PROBE WITH NPT FITTING

- SHEATH MATERIAL — STAINLESS STEEL
- SHEATH DIA. — 1/8"
- SHEATH LENGTH — 5"
- WIRE LENGTH — 12"
- TERMINATION — STRIPPED LEADS


OSK3562
\$84 each
 Plus One-Time Set-Up Charge

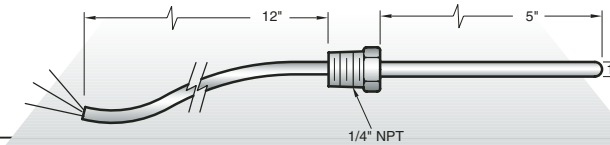

1/4" O.D. SOLID STATE SENSOR, QUICK DISCONNECT

- CALIBRATION — THERMISTOR
- JUNCTION — N/A
- SHEATH MATERIAL — 304SS
- SHEATH DIA. — 1/4"
- SHEATH LENGTH — 6"
- WIRE AWG — N/A
- WIRE LENGTH — N/A
- WIRE INSULATION — N/A
- TERMINATION — OSTW-U-M (STD. WRITE-ON)

 
OSK4119
\$84 each
 Plus One-Time Set-Up Charge



TUBULAR STAINLESS STEEL PROBE WITH PIPE FITTING

- SHEATH MATERIAL — STAINLESS STEEL
- SHEATH DIA. — 1/8"
- WIRE LENGTH — 10'
- TERMINATION — STRIPPED LEADS


OSK2085
\$136 each
 Plus One-Time Set-Up Charge

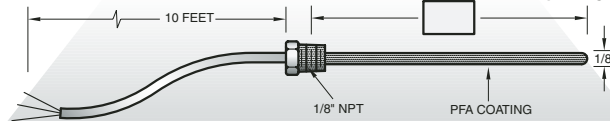

PROBE WITH 1/2" NPT FITTING AND COMPOSITE THERMISTOR ELEMENT


- SHEATH MATERIAL — 316 STAINLESS STEEL
- SHEATH DIA. — 1/4"
- SHEATH LENGTH — 4 1/2"
- WIRE AWG — 26 STRANDED
- TERMINATION — STRIPPED LEADS
- SPECIAL OPTIONS — 1/2" NPT HEAD COMPOSITE THERMISTOR ELEMENT

OSK2679
\$88 each
 Plus One-Time Set-Up Charge

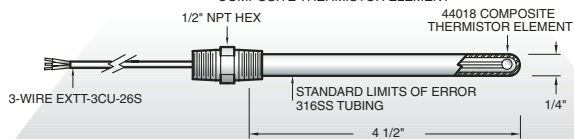


CUSTOM TEMPERED SHEATH PROBE

OSK41127
\$105 each
 Plus One-Time Set-Up Charge

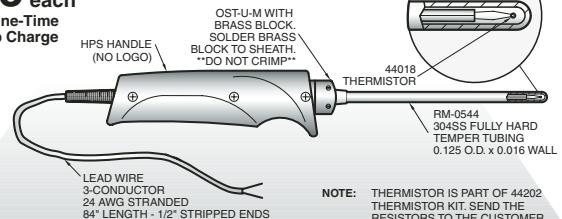

 QUICK DISCONNECT HANDLE/THERMISTOR PROBE




OSK3090
\$136 each
 Plus One-Time Set-Up Charge

- SENSOR — THERMISTOR
- SHEATH MATERIAL — 304SS
- SHEATH DIA. — 1/8"
- SHEATH LENGTH — 6"
- WIRE AWG — 26 STRANDED
- WIRE LENGTH — 60"
- WIRE INSULATION — PFA
- TERMINATION — STRIPPED LEADS

88000 SERIES HANDLE WITH THERMISTOR AND MTP MALE/FEMALE CONNECTOR TERMINATION

- SHEATH MATERIAL — 304 STAINLESS STEEL
- SHEATH DIA. — 3/16"
- SHEATH LENGTH — 5.25"
- WIRE AWG — 26
- WIRE LENGTH — 24"
- WIRE INSULATION — PFA
- TERMINATION — MTP MALE/FEMALE CONNECTOR


OSK3312
\$3 each
 Plus One-Time Set-Up Charge

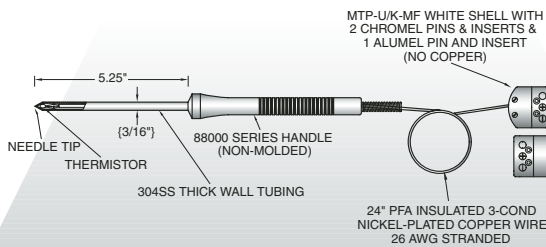

RETRACTABLE SENSOR CABLE WITH SURFACE SENSOR

- WIRE AWG — 28 STRANDED
- WIRE INSULATION — PFA
- TERMINATION — SURFACE SENSOR


NSK1013
\$53 each
 Plus One-Time Set-Up Charge

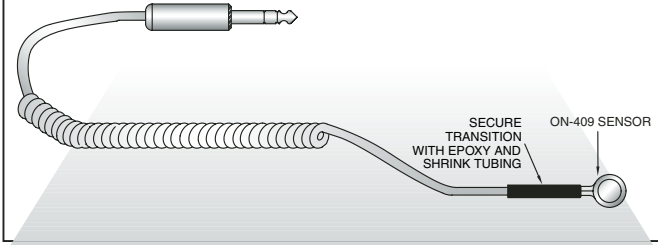

THERMISTOR WITH MOLEX CONNECTOR TERMINATION

- WIRE AWG — 26
- WIRE INSULATION — PFA WITH FIBERGLASS SLEEVING
- TERMINATION — MOLEX CONNECTORS


OSK1242
\$61 each
 Plus One-Time Set-Up Charge

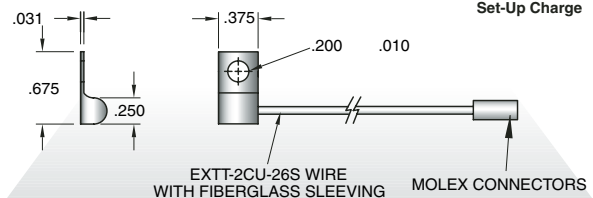

24" PENETRATION PROBE WITH HDX HANDLE

- SHEATH MATERIAL — 316 STAINLESS STEEL
- SHEATH DIA. — 1/4"
- SHEATH LENGTH — 24"
- TERMINATION — HDX HANDLE


OSK60563
\$224 each
 Plus One-Time Set-Up Charge

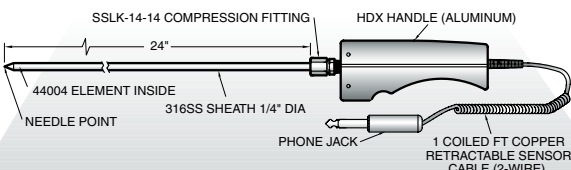

THERMISTOR PROBE WITH 1/4" NPT FITTING

- SHEATH MATERIAL — STAINLESS STEEL
- SHEATH DIA. — 1/8"
- SHEATH LENGTH — 5"
- WIRE AWG — 28
- TERMINATION — STRIPPED LEADS

 
OSK60375
\$81 each
 Plus One-Time Set-Up Charge



THERMISTOR WIRE WITH TA3F CONNECTOR TERMINATION

- WIRE LENGTH — 5.5 m (18 feet)
- TERMINATION — TA3F CONNECTOR

 
OSK22542
\$30 each
 Plus One-Time Set-Up Charge



THERMISTOR ELEMENT WITH TEFLON® INSULATED LEAD WIRES ATTACHED

- WIRE AWG — 26
- WIRE INSULATION — PFA
- TERMINATION — LEAD WIRES


OSK0451
\$55 each
 Plus One-Time Set-Up Charge

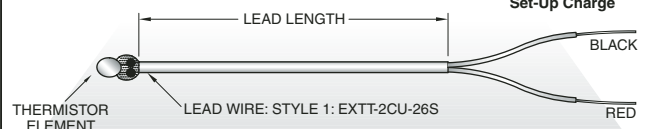

PFA INSULATED THERMISTOR PROBE WITH WHITE SHRINK TUBING


- WIRE LENGTH — 15"
- WIRE INSULATION — PFA
- TERMINATION — STRIPPED LEADS

OSK70489
\$62 each
 Plus One-Time Set-Up Charge

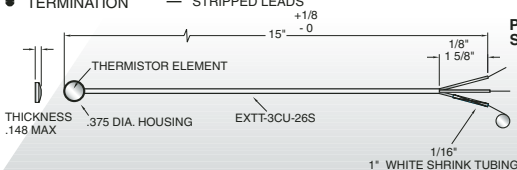

Thermistors (cont'd)


THERMISTOR GRID ASSEMBLY

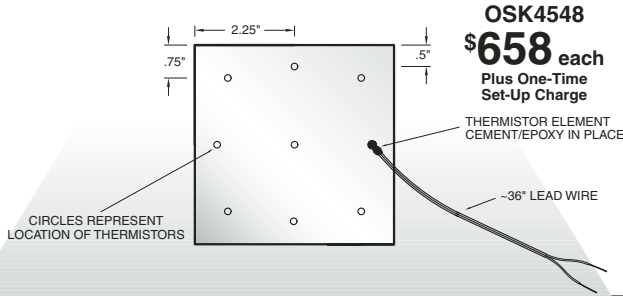

OSK4548
\$658 each
 Plus One-Time Set-Up Charge


THERMISTOR ELEMENT CEMENT/EPOXY IN PLACE

THERMISTOR WITH TRANSITION FITTING SPRING

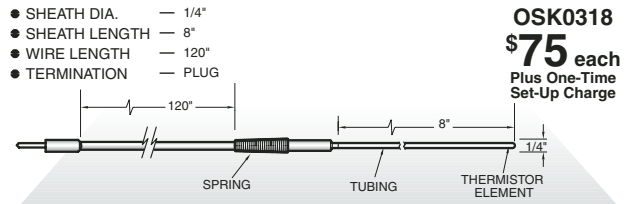


OSK0318
\$75 each
 Plus One-Time Set-Up Charge

LINEAR THERMISTOR PROBE WITH HARDENED STEEL TUBE

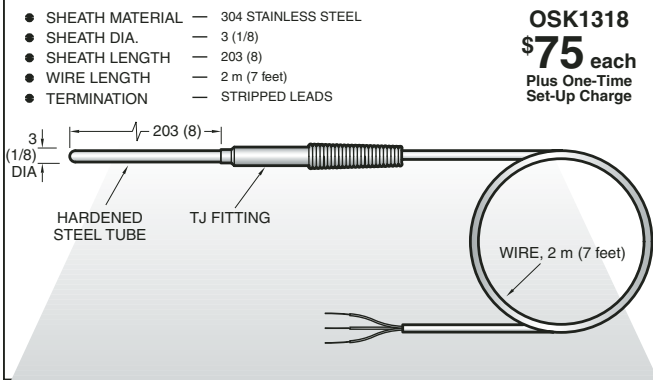

OSK1318
\$75 each
 Plus One-Time Set-Up Charge


50' PFA INSULATED THERMISTOR WIRE

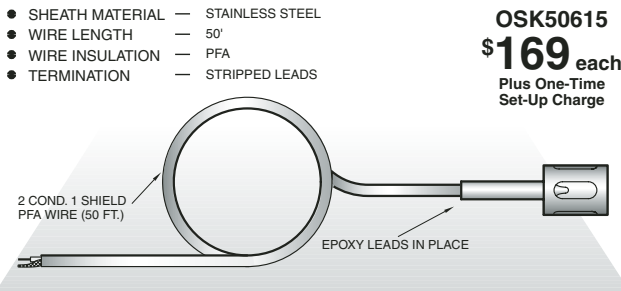

OSK50615
\$169 each
 Plus One-Time Set-Up Charge

2 COND. 1 SHIELD PFA WIRE (50 FT.)
 EPOXY LEADS IN PLACE


PFA INSULATED THERMISTOR WITH SURFACE SENSOR

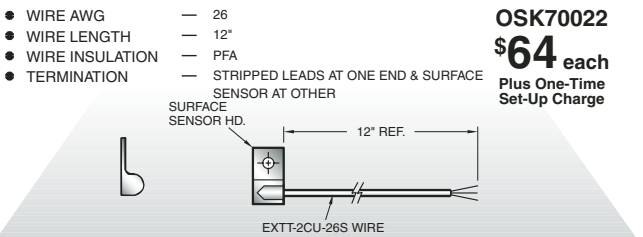

OSK70022
\$64 each
 Plus One-Time Set-Up Charge

SURFACE SENSOR AT OTHER END & SURFACE SENSOR AT OTHER
 SURFACE SENSOR HD.
 12" REF.
 EXT-2CU-26S WIRE


THERMISTOR WITH OPEN ENDED SHEATH AND TWISTED SHIELDED WIRE

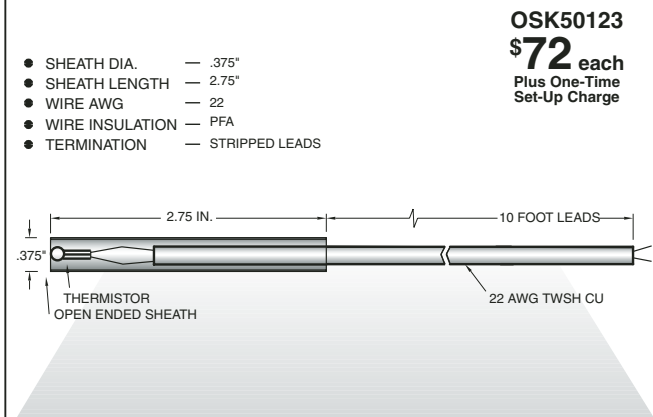

OSK50123
\$72 each
 Plus One-Time Set-Up Charge


2.75 IN.
 10 FOOT LEADS
 THERMISTOR OPEN ENDED SHEATH
 22 AWG TWSH CU

COMPOSITE THERMISTOR WITH RESISTOR BUILT INTO PROBE

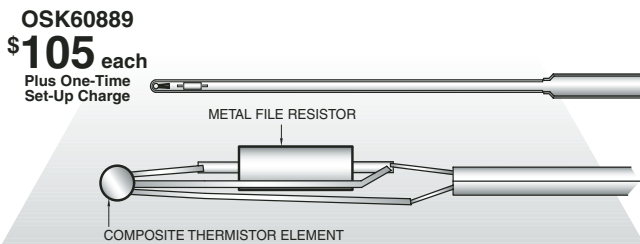

OSK60889
\$105 each
 Plus One-Time Set-Up Charge


NYLON INSULATED WIRE WITH SOLID STATE TEMPERATURE SENSOR

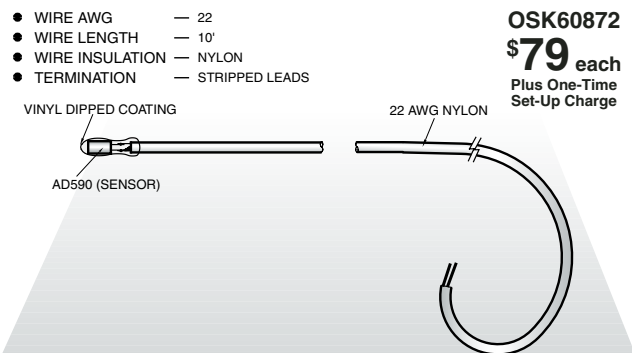

OSK60872
\$79 each
 Plus One-Time Set-Up Charge

VINYL DIPPED COATING
 AD590 (SENSOR)
 22 AWG NYLON

THERMISTOR IN BOLT HOUSING

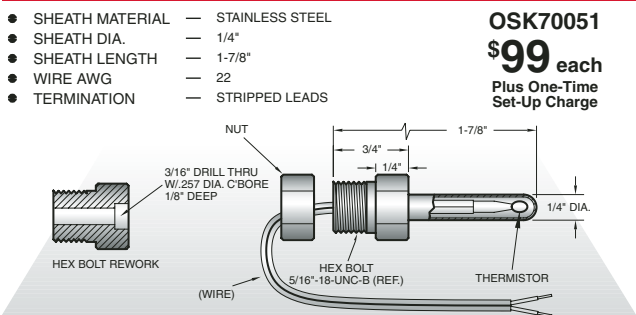

OSK70051
\$99 each
 Plus One-Time Set-Up Charge

HEX BOLT REWORK
 3/16" DRILL THRU W/.257 DIA. C'BORE 1/8" DEEP
 NUT
 3/4"
 1/4"
 1-7/8"
 HEX BOLT 5/16"-18-UNC-B (REF.)
 THERMISTOR
 (WIRE)